


H4,0/22D ZH GR SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

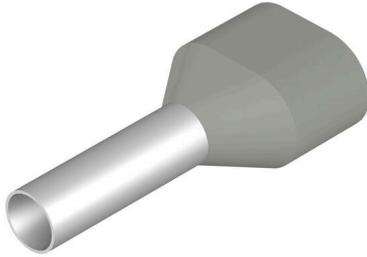

- in multi-pack bag (5 x 100 pcs.)
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, grey
Order No.	9004730000
Type	H4,0/22D ZH GR SV
GTIN (EAN)	4008 19016 1811
Qty.	100 items
Packaging	Multipack bag

H4,0/22D ZH GR SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.5 g
------------	-------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, grey	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	3.5 mm	Contact surface length (L2)	12 mm
Collar width (B)	5.2 mm	Collar height (A)	9 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	22.00 mm
Wire connection cross section AWG, max.	AWG 12	Metal sleeve thickness (S1)	0.2 mm
Stripping length	15 mm	Conductor cross-section	4 mm ²
Colour code	DIN		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

