


H0,75/16T ZH HBL SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

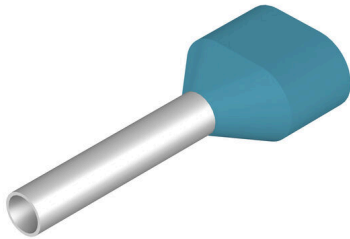

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

| | |
|------------|---|
| Version | Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, Light Blue |
| Order No. | 9005 140000 |
| Type | H0,75/16T ZH HBL SV |
| GTIN (EAN) | 4008 190482725 |
| Qty. | 500 items |
| Packaging | Multipack bag |

H0,75/16T ZH HBL SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 0.15 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Technical data

| Description of article | Twin wire end ferrule, light blue | Version | Twin wire-end ferrule |
|------------------------|-----------------------------------|---------|-----------------------|
|------------------------|-----------------------------------|---------|-----------------------|

Wire-end ferrules

| | | | |
|---|---------------|-----------------------------|----------------------|
| Contact surface diameter (D1) | 1.7 mm | Contact surface length (L2) | 10 mm |
| Collar width (B) | 3 mm | Collar height (A) | 5.5 mm |
| Plastic collar thickness (S2) | 0.3 mm | L1 in mm | 16.00 mm |
| Wire connection cross section AWG, max. | AWG 18 | Metal sleeve thickness (S1) | 0.15 mm |
| Stripping length | 13 mm | Conductor cross-section | 0.75 mm ² |
| Colour code | Telemecanique | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Drawing

