


## H6,0/23T ZH GN SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

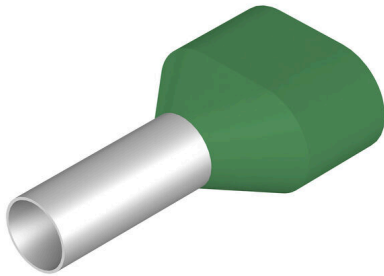

- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, green
Order No.	<a href="#">9005 160000</a>
Type	H6,0/23T ZH GN SV
GTIN (EAN)	4008 190482749
Qty.	100 items
Packaging	Multipack bag

H6,0/23T ZH GN SV

Weidmüller Interface GmbH & Co. KG  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.69 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, green	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	4.5 mm	Contact surface length (L2)	12 mm
Collar width (B)	6.2 mm	Collar height (A)	11.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	23.00 mm
Wire connection cross section AWG, max.	AWG 10	Metal sleeve thickness (S1)	0.2 mm
Stripping length	20 mm	Conductor cross-section	6 mm <sup>2</sup>
Colour code	Telemecanique		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

