


H2,5/21,5X BL SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

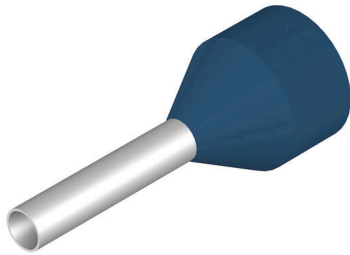

- supplied loose in polybag
- Weidmüller colour code

General ordering data

Version	Wire-end ferrule, Standard, 17 mm, 12 mm, blue
Order No.	9006710000
Type	H2,5/21,5X BL SV
GTIN (EAN)	4008190332280
Qty.	100 items
Packaging	Multipack bag

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.3 g
------------	-------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule for short-circuit-proof and earth-fault-proof lines, blue	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	2.3 mm	Contact surface length (L2)	12 mm
Collar diameter (D2)	7.9 mm	Plastic collar thickness (S2)	0.3 mm
L1 in mm	21.50 mm	Wire connection cross section AWG, max.	AWG 14
Metal sleeve thickness (S1)	0.15 mm	Stripping length	17 mm
Conductor cross-section	2.5 mm ²	Colour code	Weidmueller

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

