

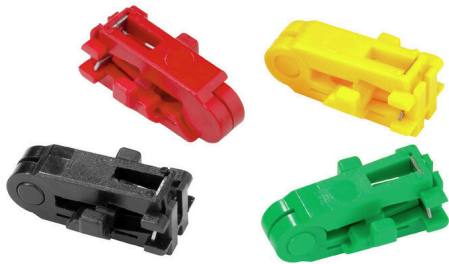
MEHA KP WS M-D-SPX**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

- Flexible and solid wire with PVC, Teflon (PTFE) and silicone insulation
- No damage to the wire thanks to specially shaped blade
- No splicing of individual wires
- Blade inserts are easy to replace
- All inserts fit one housing
- Guide bars in the blade cassettes facilitate correct positioning of the wire in the tool

General ordering data

Version	Accessories, Set of cutters
Order No.	9006970000
Type	MEHA KP WS M-D-SPX
GTIN (EAN)	4032248363711
Qty.	1 items

MEHA KP WS M-D-SPX

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	16 mm	Depth (inches)	0.6299 inch
Height	11.5 mm	Height (inches)	0.4528 inch
Width	26 mm	Width (inches)	1.0236 inch
Length	26 mm	Length (inches)	1.0236 inch
Net weight	3.68 g		

Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	Lead 7439-92-1
SCIP	cf06c250-ed1e-4a45-9c1b-c5c8cbf13bf0

Technical data

Description of article	Set of blades for Mini-Duro-Stripax up to 1mm ² for PVC/silicone
------------------------	---

Stripping tools

Cable type	Flexible and solid conductors with PVC insulation	Max. conductor diameter	1.3 mm
Min. conductor diameter	0.3 mm	Stripping length, max.	7 mm
Stripping length, min.	3 mm	Colour	white

Classifications

ETIM 8.0	EC001509	ETIM 9.0	EC001509
ETIM 10.0	EC001509	ECLASS 14.0	21-04-48-91
ECLASS 15.0	21-04-48-91		