


## H0,75/14D ZH GR SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

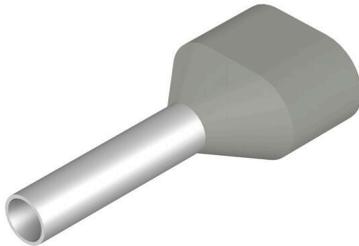

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

|            |  |
|------------|--|
| Version    | Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, grey |
| Order No.  | <a href="#">9018520000</a>                                 |
| Type       | H0,75/14D ZH GR SV   |
| GTIN (EAN) | 4008 190097998   |
| Qty.       | 500 items  |
| Packaging  | Multipack bag  |

**Technical data**

**Approvals**

Approvals



|                         |                            |
|-------------------------|----------------------------|
| ROHS                    | Conform                    |
| UL File Number Search   | <a href="#">UL Website</a> |
| Certificate no. (cULus) | E499744                    |

**Dimensions and weights**

|            |        |
|------------|--------|
| Net weight | 0.14 g |
|------------|--------|

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

**Technical data**

|                        |                             |         |                       |
|------------------------|-----------------------------|---------|-----------------------|
| Description of article | Twin wire end ferrule, grey | Version | Twin wire-end ferrule |
|------------------------|-----------------------------|---------|-----------------------|

**Wire-end ferrules**

|   |        |                             |                      |
|---|--------|-----------------------------|----------------------|
| Contact surface diameter (D1)           | 1.7 mm | Contact surface length (L2) | 8 mm                 |
| Collar width (B)                        | 3 mm   | Collar height (A)           | 5.5 mm               |
| Plastic collar thickness (S2)           | 0.3 mm | L1 in mm                    | 14.00 mm             |
| Wire connection cross section AWG, max. | AWG 18 | Metal sleeve thickness (S1) | 0.15 mm              |
| Stripping length                        | 11 mm  | Conductor cross-section     | 0.75 mm <sup>2</sup> |
| Colour code                             | DIN    |                             |                      |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000005    | ETIM 9.0    | EC000005    |
| ETIM 10.0   | EC000005    | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 |             |             |

Drawing

