


## H0,75/15T ZH BL SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

### Similar to illustration

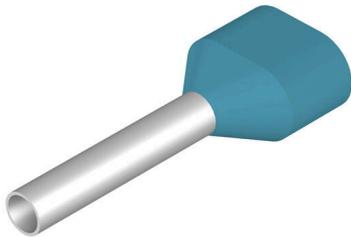

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, Light Blue
Order No.	<a href="#">9018570000</a>
Type	H0,75/15T ZH BL SV
GTIN (EAN)	4008190272630
Qty.	500 items
Packaging	Multipack bag

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.14 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, blue	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar width (B)	3 mm	Collar height (A)	5.5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	15.00 mm
Wire connection cross section AWG, max.	AWG 18	Metal sleeve thickness (S1)	0.15 mm
Stripping length	11 mm	Conductor cross-section	0.75 mm <sup>2</sup>
Colour code	Telemecanique		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

