


**H1,0/15S ZH GE SV****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

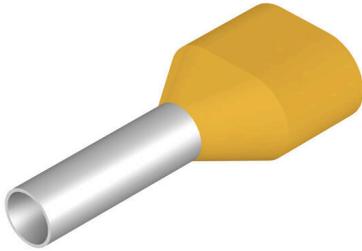

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, yellow
Order No.	<a href="#">9018650000</a>
Type	H1,0/15S ZH GE SV
GTIN (EAN)	4032248011407
Qty.	500 items
Packaging	Multipack bag

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Net weight 0.17 g

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, yellow	Version	Twin wire-end ferrule
------------------------	-------------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	2.2 mm	Contact surface length (L2)	8 mm
Collar width (B)	3.2 mm	Collar height (A)	5.8 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	15.00 mm
Wire connection cross section AWG, max.	AWG 17	Metal sleeve thickness (S1)	0.15 mm
Stripping length	12 mm	Conductor cross-section	1 mm <sup>2</sup>
Colour code	Weidmueller		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

**Drawing**

