


H1,0/15S ZH GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

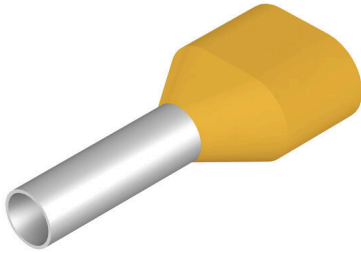

- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
Material: E-Cu, tin galvanised
Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

| | |
|------------|--|
| Version | Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, yellow |
| Order No. | 9018690000 |
| Type | H1,0/15S ZH GE |
| GTIN (EAN) | 4032248017720 |
| Qty. | 500 items |
| Packaging | loose |

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 0.16 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Technical data

| Description of article | Twin wire end ferrule, yellow | Version | Twin wire-end ferrule |
|------------------------|-------------------------------|---------|-----------------------|
|------------------------|-------------------------------|---------|-----------------------|

Wire-end ferrules

| | | | |
|---|-------------|-----------------------------|-------------------|
| Contact surface diameter (D1) | 2.3 mm | Contact surface length (L2) | 8 mm |
| Collar width (B) | 3.6 mm | Collar height (A) | 6.5 mm |
| Plastic collar thickness (S2) | 0.3 mm | L1 in mm | 15.00 mm |
| Wire connection cross section AWG, max. | AWG 17 | Metal sleeve thickness (S1) | 0.15 mm |
| Stripping length | 12 mm | Conductor cross-section | 1 mm ² |
| Colour code | Weidmueller | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Drawing

