


## H10,0/24S ZH EB

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

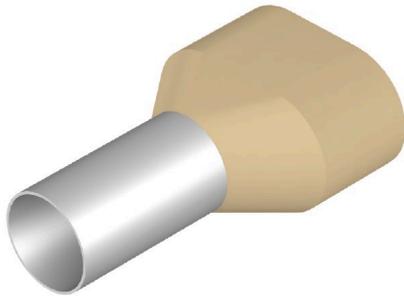

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, Ivory
Order No.	<a href="#">9018860000</a>
Type	H10,0/24S ZH EB
GTIN (EAN)	4032248105816
Qty.	100 items
Packaging	loose

**H10,0/24S ZH EB**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Net weight	0.82 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, ivory	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	6.5 mm	Contact surface length (L2)	12 mm
Collar width (B)	7.6 mm	Collar height (A)	13.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	24.00 mm
Wire connection cross section AWG, max.	AWG 8	Metal sleeve thickness (S1)	0.2 mm
Stripping length	17 mm	Conductor cross-section	10 mm <sup>2</sup>
Colour code	Weidmueller		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

