


**H10,0/30S ZH EB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

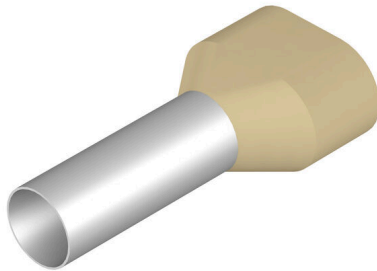

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Twin wire-end ferrule, 23 mm, 18 mm, Ivory
Order No.	<a href="#">9018870000</a>
Type	H10,0/30S ZH EB
GTIN (EAN)	4032248105823
Qty.	100 items
Packaging	loose

**H10,0/30S ZH EB**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Net weight 1.07 g

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Technical data**

Description of article Twin wire end ferrule, ivory Version Twin wire-end ferrule

**Wire-end ferrules**

Contact surface diameter (D1)	6.5 mm	Contact surface length (L2)	18 mm
Collar width (B)	7.6 mm	Collar height (A)	13.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	30.00 mm
Wire connection cross section AWG, max.	AWG 8	Metal sleeve thickness (S1)	0.2 mm
Stripping length	23 mm	Conductor cross-section	10 mm <sup>2</sup>
Colour code	Weidmueller		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

