


**H10,0/30S ZH EB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

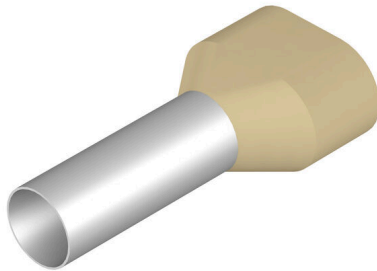

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

|            |  |
|------------|--|
| Version    | Wire-end ferrule, Twin wire-end ferrule, 23 mm, 18 mm, Ivory |
| Order No.  | <a href="#">9018870000</a>                                   |
| Type       | H10,0/30S ZH EB  |
| GTIN (EAN) | 4032248105823  |
| Qty.       | 100 items  |
| Packaging  | loose  |

**H10,0/30S ZH EB**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

**Dimensions and weights**

|            |        |
|------------|--------|
| Net weight | 1.07 g |
|------------|--------|

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

**Technical data**

|                        |                              |         |                       |
|------------------------|------------------------------|---------|-----------------------|
| Description of article | Twin wire end ferrule, ivory | Version | Twin wire-end ferrule |
|------------------------|------------------------------|---------|-----------------------|

**Wire-end ferrules**

|   |             |                             |                    |
|---|-------------|-----------------------------|--------------------|
| Contact surface diameter (D1)           | 6.5 mm      | Contact surface length (L2) | 18 mm              |
| Collar width (B)                        | 7.6 mm      | Collar height (A)           | 13.4 mm            |
| Plastic collar thickness (S2)           | 0.5 mm      | L1 in mm                    | 30.00 mm           |
| Wire connection cross section AWG, max. | AWG 8       | Metal sleeve thickness (S1) | 0.2 mm             |
| Stripping length                        | 23 mm       | Conductor cross-section     | 10 mm <sup>2</sup> |
| Colour code                             | Weidmueller |                             |                    |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000005    | ETIM 9.0    | EC000005    |
| ETIM 10.0   | EC000005    | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 |             |             |

**Drawing**

