


H10,0/30S ZH EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

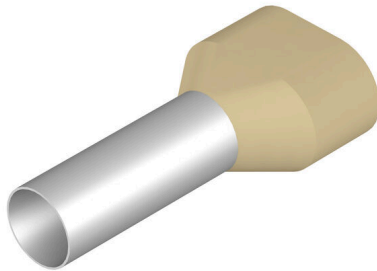

- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
Material: E-Cu, tin galvanised
Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 23 mm, 18 mm, Ivory
Order No.	9018870000
Type	H10,0/30S ZH EB
GTIN (EAN)	4032248105823
Qty.	100 items
Packaging	loose

H10,0/30S ZH EB

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Net weight	1.07 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, ivory	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	6.5 mm	Contact surface length (L2)	18 mm
Collar width (B)	7.6 mm	Collar height (A)	13.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	30.00 mm
Wire connection cross section AWG, max.	AWG 8	Metal sleeve thickness (S1)	0.2 mm
Stripping length	23 mm	Conductor cross-section	10 mm ²
Colour code	Weidmueller		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

