


**H10,0/30DS ZH R****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

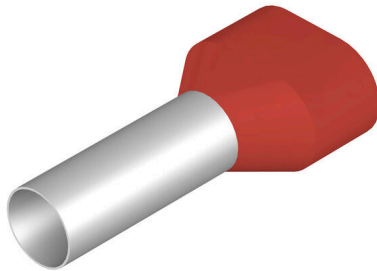

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Twin wire-end ferrule, 23 mm, 18 mm, red
Order No.	<a href="#">9018890000</a>
Type	H10,0/30DS ZH R
GTIN (EAN)	4032248105847
Qty.	100 items
Packaging	loose

**H10,0/30DS ZH R**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Net weight	0.91 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, red	Version	Twin wire-end ferrule
------------------------	----------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	6.5 mm	Contact surface length (L2)	18 mm
Collar width (B)	7.6 mm	Collar height (A)	13.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	30.00 mm
Wire connection cross section AWG, max.	AWG 8	Metal sleeve thickness (S1)	0.2 mm
Stripping length	23 mm	Conductor cross-section	10 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

