


## H1,0/12D R

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

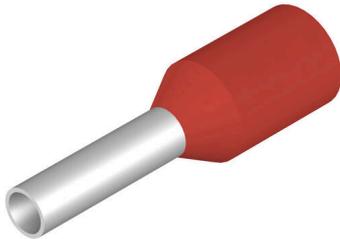

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Standard, 8 mm, 6 mm, red
Order No.	<a href="#">9019070000</a>
Type	H1,0/12D R
GTIN (EAN)	4008 190029074
Qty.	500 items
Packaging	loose

**H1,0/12D R**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.08 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, red	Version	Standard
------------------------	-------------------------------------------	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	1.4 mm	Contact surface length (L2)	6 mm
Collar diameter (D2)	3 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	12.00 mm	Wire connection cross section AWG, max.	AWG 17
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 008 A
Stripping length	8 mm	Conductor cross-section	1 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

