


**H1,0/14D R****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

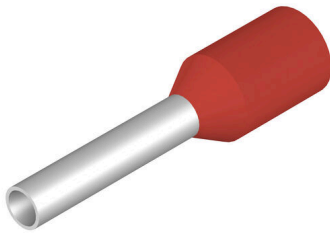

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

**General ordering data**

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, red
Order No.	<a href="#">9019080000</a>
Type	H1,0/14D R
GTIN (EAN)	4008 190090623
Qty.	500 items
Packaging	loose

H1,0/14D R

Weidmüller Interface GmbH & Co. KG  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.1 g
------------	-------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, red	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	1.4 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	3 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 17
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 009 A
Stripping length	10 mm	Conductor cross-section	1 mm <sup>2</sup>
Colour code	DIN		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

