


H6,0/26D GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

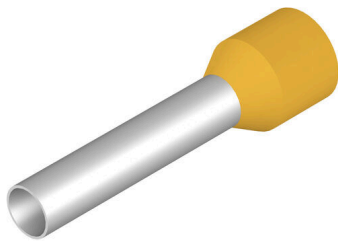

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 20 mm, 18 mm, yellow
Order No.	9019230000
Type	H6,0/26D GE
GTIN (EAN)	4008190072117
Qty.	100 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.5 g
------------	-------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	3.5 mm	Contact surface length (L2)	18 mm
Collar diameter (D2)	6.3 mm	Plastic collar thickness (S2)	0.3 mm
L1 in mm	26.00 mm	Wire connection cross section AWG, max.	AWG 10
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 023 A
Stripping length	20 mm	Conductor cross-section	6 mm ²
Colour code	DIN		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

