


## H10,0/28D R

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

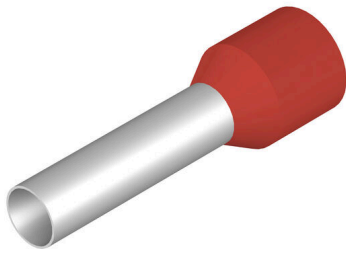

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 21 mm, 18 mm, red
Order No.	<a href="#">9019250000</a>
Type	H10,0/28D R
GTIN (EAN)	4008 19004 1410
Qty.	100 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.62 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, red	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	4.5 mm	Contact surface length (L2)	18 mm
Collar diameter (D2)	7.6 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	28.00 mm	Wire connection cross section AWG, max.	AWG 8
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 025 A
Stripping length	21 mm	Conductor cross-section	10 mm <sup>2</sup>
Colour code	DIN		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

