

H16,0/22D BL


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

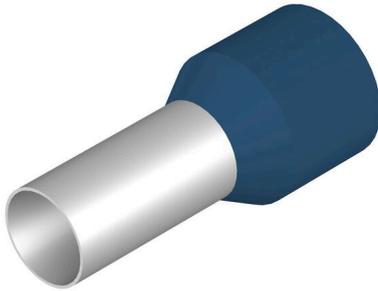

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 15 mm, 12 mm, blue
Order No.	9019260000
Type	H16,0/22D BL
GTIN (EAN)	4008 190125806
Qty.	100 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.67 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, blue	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	5.8 mm	Contact surface length (L2)	12 mm
Collar diameter (D2)	8.8 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	22.00 mm	Wire connection cross section AWG, max.	AWG 6
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 026 A
Stripping length	15 mm	Conductor cross-section	16 mm ²
Colour code	DIN		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

