


## H25,0/30D 16 GE

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

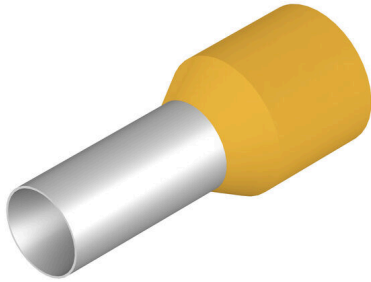

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 18 mm, 16 mm, yellow
Order No.	<a href="#">9019280000</a>
Type	H25,0/30D 16 GE
GTIN (EAN)	4008 190038380
Qty.	50 items
Packaging	loose

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	1.19 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	7.3 mm	Contact surface length (L2)	16 mm
Collar diameter (D2)	11.2 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	30.00 mm	Wire connection cross section AWG, max.	AWG 3
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 028 A
Stripping length	18 mm	Conductor cross-section	25 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

