


## H1,5/14D SW SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

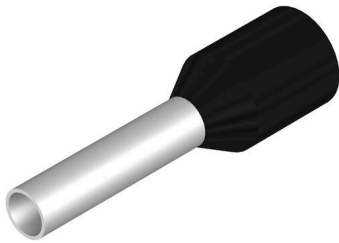

- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, black
Order No.	<a href="#">9019430000</a>
Type	H1,5/14D SW SV
GTIN (EAN)	4008 190107420
Qty.	500 items
Packaging	Multipack bag

**H1,5/14D SW SV**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.13 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, black	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	3.5 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 16
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 012 A
Stripping length	10 mm	Conductor cross-section	1.5 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

