


H2,5/25T GR

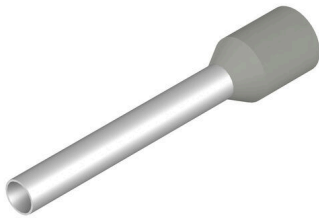

- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

| | |
|------------|--|
| Version | Wire-end ferrule, Standard, 20 mm, 18 mm, grey |
| Order No. | 9021090000 |
| Type | H2,5/25T GR |
| GTIN (EAN) | 4008190060916 |
| Qty. | 500 items |
| Packaging | loose |

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.24 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

| Description of article | Wire end ferrule with plastic collar, grey | Version | Standard |
|------------------------|--|---------|----------|
|------------------------|--|---------|----------|

Wire-end ferrules

| | | | |
|-------------------------------|---------------------|---|---------------|
| Contact surface diameter (D1) | 2.2 mm | Contact surface length (L2) | 18 mm |
| Collar diameter (D2) | 4.2 mm | Plastic collar thickness (S2) | 0.25 mm |
| L1 in mm | 25.00 mm | Wire connection cross section AWG, max. | AWG 14 |
| Metal sleeve thickness (S1) | 0.15 mm | Stripping length | 20 mm |
| Conductor cross-section | 2.5 mm ² | Colour code | Telemecanique |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Drawing

