


## H6,0/26T GN

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

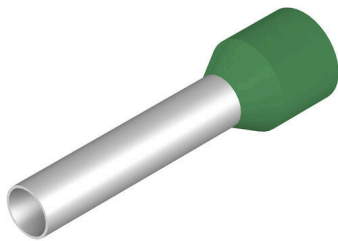

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 20 mm, 18 mm, green
Order No.	<a href="#">9021140000</a>
Type	H6,0/26T GN
GTIN (EAN)	4008190022501
Qty.	100 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.5 g
------------	-------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, green	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	3.5 mm	Contact surface length (L2)	18 mm
Collar diameter (D2)	6.3 mm	Plastic collar thickness (S2)	0.3 mm
L1 in mm	26.00 mm	Wire connection cross section AWG, max.	AWG 10
Metal sleeve thickness (S1)	0.2 mm	Stripping length	20 mm
Conductor cross-section	6 mm <sup>2</sup>	Colour code	Telemecanique

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

