


## H10,0/28T BR

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

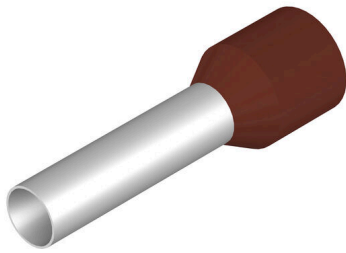

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 21 mm, 18 mm, brown
Order No.	<a href="#">9021160000</a>
Type	H10,0/28T BR
GTIN (EAN)	4008190041915
Qty.	100 items
Packaging	loose

## Technical data

### Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

### Dimensions and weights

Net weight 0.68 g

### Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

### Technical data

Description of article	Wire end ferrule with plastic collar, brown	Version	Standard
------------------------	---	---------	----------

### Wire-end ferrules

Contact surface diameter (D1)	4.5 mm	Contact surface length (L2)	18 mm
Collar diameter (D2)	7.6 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	28.00 mm	Wire connection cross section AWG, max.	AWG 8
Metal sleeve thickness (S1)	0.2 mm	Stripping length	21 mm
Conductor cross-section	10 mm <sup>2</sup>	Colour code	Telemecanique

### Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

