


H16,0/28T W

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

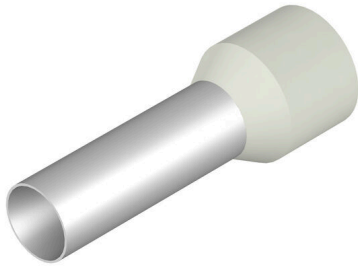

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 21 mm, 18 mm, white
Order No.	9021180000
Type	H16,0/28T W
GTIN (EAN)	4008190151980
Qty.	100 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.88 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, white	Version	Standard
------------------------	---------------------------------------------	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	5.8 mm	Contact surface length (L2)	18 mm
Collar diameter (D2)	8.8 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	28.00 mm	Wire connection cross section AWG, max.	AWG 6
Metal sleeve thickness (S1)	0.2 mm	Stripping length	21 mm
Conductor cross-section	16 mm ²	Colour code	Telemecanique

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

