


## H25,0/36T SW

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

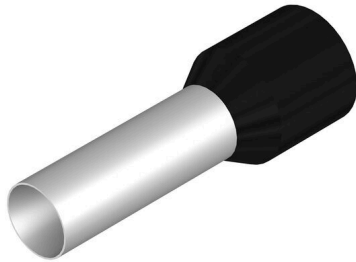

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 24 mm, 22 mm, black
Order No.	<a href="#">9021200000</a>
Type	H25,0/36T SW
GTIN (EAN)	4008 190055400
Qty.	50 items
Packaging	loose

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	1.44 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, black	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	7.3 mm	Contact surface length (L2)	22 mm
Collar diameter (D2)	11.2 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	36.00 mm	Wire connection cross section AWG, max.	AWG 3
Metal sleeve thickness (S1)	0.2 mm	Stripping length	24 mm
Conductor cross-section	25 mm <sup>2</sup>	Colour code	Telemecanique

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

