


## H0,25/10T GE SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

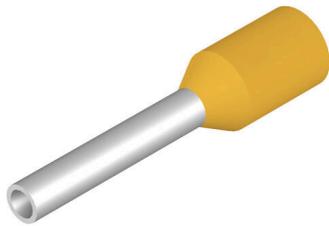

- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

### General ordering data

Version	Wire-end ferrule, Standard, 8 mm, 6 mm, yellow
Order No.	<a href="#">9021210000</a>
Type	H0,25/10T GE SV
GTIN (EAN)	4008 190045555
Qty.	500 items
Packaging	Multipack bag

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Net weight	0.06 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	0.8 mm	Contact surface length (L2)	6 mm
Collar diameter (D2)	1.8 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	10.00 mm	Wire connection cross section AWG, max.	AWG 24
Metal sleeve thickness (S1)	0.15 mm	Stripping length	8 mm
Conductor cross-section	0.25 mm <sup>2</sup>	Colour code	Telemecanique

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

