


## H0,75/14T HBL SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

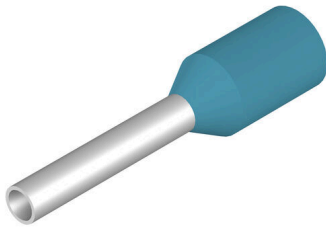

- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue
Order No.	<a href="#">9021230000</a>
Type	H0,75/14T HBL SV
GTIN (EAN)	4008190153106
Qty.	500 items
Packaging	Multipack bag

## H0,75/14T HBL SV

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

## Dimensions and weights

Net weight 0.1 g

## Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

## Technical data

Description of article	Wire end ferrule with plastic collar, light blue	Version	Standard
------------------------	--	---------	----------

## Wire-end ferrules

Contact surface diameter (D1)	1.2 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	2.8 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 18
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	0.75 mm <sup>2</sup>	Colour code	Telemecanique

## Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

