


## H2,5/15T GR SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

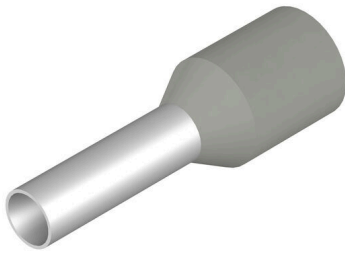

- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
Order No.	<a href="#">9021240000</a>
Type	H2,5/15T GR SV
GTIN (EAN)	4008 1901 15302
Qty.	500 items
Packaging	Multipack bag

**H2,5/15T GR SV**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.16 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, grey	Version	Standard
------------------------	--	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	2.2 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	4.2 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	15.00 mm	Wire connection cross section AWG, max.	AWG 14
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	2.5 mm <sup>2</sup>	Colour code	Telemecanique

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

