


H0,5/14T W BD

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration

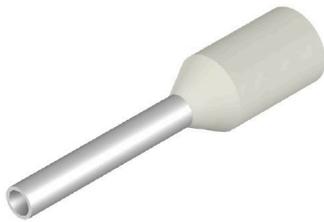

- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, white
Order No.	9021930000
Type	H0,5/14T W BD
GTIN (EAN)	4008 190262402
Qty.	500 items
Packaging	Reel packaged

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 0.07 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Strip of wire end ferrules, white	Version	Standard
------------------------	-----------------------------------	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	1 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	3.3 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	15.00 mm	Wire connection cross section AWG, max.	AWG 20
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	0.5 mm ²	Colour code	Telemecanique

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01
ECLASS 13.0	27-40-02-01	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

