


## H1,5/14T SW BD

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

### Similar to illustration

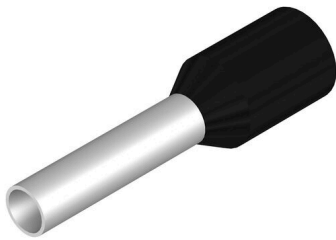

- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, black
Order No.	<a href="#">9021960000</a>
Type	H1,5/14T SW BD
GTIN (EAN)	4008190262389
Qty.	500 items
Packaging	Reel packaged

**H1,5/14T SW BD**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Net weight	0.1 g
------------	-------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Linked wire-end ferrules, black	Version	Standard
------------------------	------------------------------------	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	3.9 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	15.00 mm	Wire connection cross section AWG, max.	AWG 16
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	1.5 mm <sup>2</sup>	Colour code	Telemecanique

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

