

## H1,5/14DS SW


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

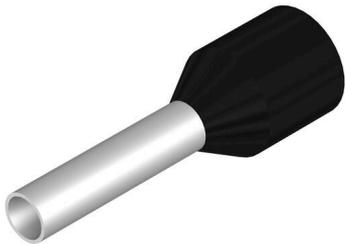

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, black
Order No.	<a href="#">9025240000</a>
Type	H1,5/14DS SW
GTIN (EAN)	4008 190085599
Qty.	500 items
Packaging	loose

## H1,5/14DS SW

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

### Dimensions and weights

Net weight 0.12 g

### Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

### Technical data

Description of article	Wire end ferrule with plastic collar, special size, black	Version	Standard

### Wire-end ferrules

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	4 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 16
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	1.5 mm <sup>2</sup>	Colour code	Weidmueller

### Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

