


## H1,0/14S GE SV

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

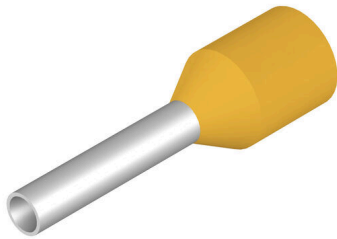

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
Order No.	<a href="#">9025710000</a>
Type	H1,0/14S GE SV
GTIN (EAN)	4008190031442
Qty.	500 items
Packaging	Multipack bag

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.12 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, special size, yellow	Version	Standard
------------------------	--	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	1.4 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	3.5 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 17
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	1 mm <sup>2</sup>	Colour code	Weidmueller

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

