


H0,34/12 TK SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

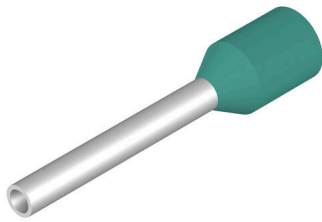

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code

General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, Turquoise
Order No.	9025790000
Type	H0,34/12 TK SV
GTIN (EAN)	4008 190121 174
Qty.	500 items
Packaging	Multipack bag

H0,34/12 TK SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Net weight	0.06 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, turquoise	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	0.8 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	2 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	12.00 mm	Wire connection cross section AWG, max.	AWG 22
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	0.34 mm ²	Colour code	Weidmueller

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

