


## H0,34/10 TK SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

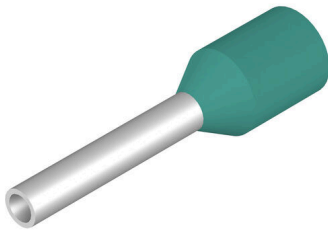

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code

### General ordering data

Version	Wire-end ferrule, Standard, 8 mm, 6 mm, Turquoise
Order No.	<a href="#">9026030000</a>
Type	H0,34/10 TK SV
GTIN (EAN)	4008 190177 171
Qty.	500 items
Packaging	Multipack bag

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Net weight	0.05 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, turquoise	Version	Standard
------------------------	-------------------------------------------------	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	0.8 mm	Contact surface length (L2)	6 mm
Collar diameter (D2)	2 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	10.00 mm	Wire connection cross section AWG, max.	AWG 22
Metal sleeve thickness (S1)	0.15 mm	Stripping length	8 mm
Conductor cross-section	0.34 mm <sup>2</sup>	Colour code	Weidmueller

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

