

## H95,0/44 R


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

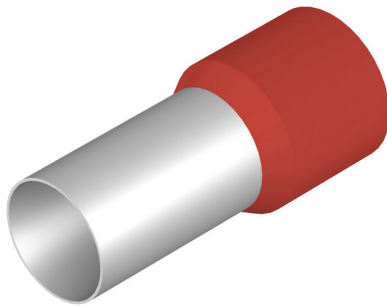

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

### General ordering data

|            |                                               |
|------------|-----------------------------------------------|
| Version    | Wire-end ferrule, Standard, 31 mm, 25 mm, red |
| Order No.  | <a href="#">9028210000</a>                    |
| Type       | H95,0/44 R                                    |
| GTIN (EAN) | 4008190891589                                 |
| Qty.       | 25 items                                      |
| Packaging  | loose                                         |

## H95,0/44 R

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

## Dimensions and weights

Net weight 5.2 g

## Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

## Technical data

| Description of article | Wire end ferrule with plastic collar, red | Version | Standard |
|------------------------|-------------------------------------------|---------|----------|
|------------------------|-------------------------------------------|---------|----------|

## Wire-end ferrules

|                               |                    |                                         |             |
|-------------------------------|--------------------|-----------------------------------------|-------------|
| Contact surface diameter (D1) | 14.7 mm            | Contact surface length (L2)             | 25 mm       |
| Collar diameter (D2)          | 18 mm              | Plastic collar thickness (S2)           | 0.6 mm      |
| L1 in mm                      | 44.00 mm           | Wire connection cross section AWG, max. | AWG 3/0     |
| Metal sleeve thickness (S1)   | 0.35 mm            | Stripping length                        | 31 mm       |
| Conductor cross-section       | 95 mm <sup>2</sup> | Colour code                             | Weidmueller |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000005    | ETIM 9.0    | EC000005    |
| ETIM 10.0   | EC000005    | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 |             |             |

## Drawing

