


## H0,14/10T BR SV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

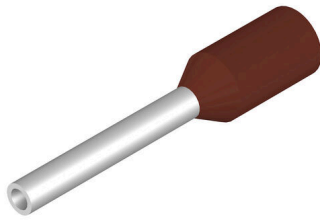

- Weidmüller colour code
- in multipack bag ( 5 x 100 pcs.)

### General ordering data

Version	Wire-end ferrule, Standard, 8 mm, 6 mm, brown
Order No.	<a href="#">9028250000</a>
Type	H0,14/10T BR SV
GTIN (EAN)	4008 190902018
Qty.	500 items
Packaging	Multipack bag

**H0,14/10T BR SV**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Net weight 0.05 g

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, brown	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	0.6 mm	Contact surface length (L2)	6 mm
Collar diameter (D2)	1.5 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	10.00 mm	Wire connection cross section AWG, max.	AWG 26
Metal sleeve thickness (S1)	0.15 mm	Stripping length	8 mm
Conductor cross-section	0.14 mm <sup>2</sup>	Colour code	Telemecanique

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

