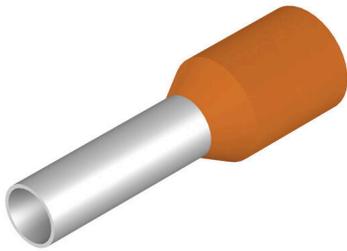


**H4,0/15TS OR**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Similar to illustration**

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
Order No.	<a href="#">9036230000</a>
Type	H4,0/15TS OR
GTIN (EAN)	4032248068029
Qty.	500 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E354986

Dimensions and weights

Net weight	0.22 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, special size, orange	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	2.8 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	4.8 mm	Plastic collar thickness (S2)	0.3 mm
L1 in mm	15.00 mm	Wire connection cross section AWG, max.	AWG 12
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 023 A
Stripping length	10 mm	Conductor cross-section	4 mm <sup>2</sup>

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

