


H1,0/22DS R ZH

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

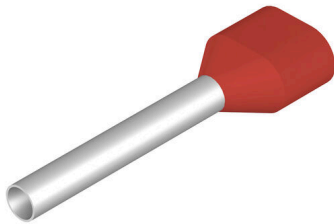

- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
Material: E-Cu, tin galvanised
Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 14 mm, red
Order No.	9036330000
Type	H1,0/22DS R ZH
GTIN (EAN)	4032248338566
Qty.	500 items
Packaging	loose

H1,0/22DS R ZH

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986

Dimensions and weights

Net weight	0.18 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, red	Version	Twin wire-end ferrule
------------------------	----------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	2 mm	Contact surface length (L2)	14 mm
Collar width (B)	3.2 mm	Collar height (A)	5.8 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	22.00 mm
Wire connection cross section AWG, max.	AWG 17	Metal sleeve thickness (S1)	0.15 mm
Stripping length	21 mm	Conductor cross-section	1 mm ²

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

