

## H0,75/14 ZH W


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

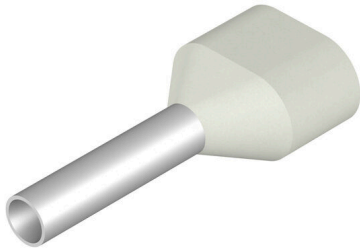

For the following conductors: 2 No. 0.75 mm<sup>2</sup> (2 No. AWG 18)

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, white
Order No.	<a href="#">9037230000</a>
Type	H0,75/14 ZH W
GTIN (EAN)	4008 190853976
Qty.	500 items
Packaging	loose

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

## Dimensions and weights

Net weight 0.11 g

## Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

## Technical data

Description of article	Twin wire end ferrule, white	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

## Wire-end ferrules

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar width (B)	3 mm	Collar height (A)	5.5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	14.00 mm
Wire connection cross section AWG, max.	AWG 18	Metal sleeve thickness (S1)	0.15 mm
Stripping length	11 mm	Conductor cross-section	0.75 mm <sup>2</sup>
Colour code	Weidmueller		

## Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

