


H6,0/29 ZH SW

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

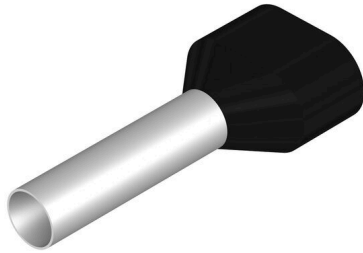

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

| | |
|------------|--|
| Version | Wire-end ferrule, Twin wire-end ferrule, 24 mm, 18 mm, black |
| Order No. | 9037330000 |
| Type | H6,0/29 ZH SW |
| GTIN (EAN) | 4008 190492809 |
| Qty. | 100 items |
| Packaging | loose |

H6,0/29 ZH SW

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.76 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

| Description of article | Twin wire end ferrule, black | Version | Twin wire-end ferrule |
|------------------------|------------------------------|---------|-----------------------|
|------------------------|------------------------------|---------|-----------------------|

Wire-end ferrules

| | | | |
|---|-------------|-----------------------------|-------------------|
| Contact surface diameter (D1) | 4.5 mm | Contact surface length (L2) | 18 mm |
| Collar width (B) | 6.2 mm | Collar height (A) | 11.4 mm |
| Plastic collar thickness (S2) | 0.5 mm | L1 in mm | 29.00 mm |
| Wire connection cross section AWG, max. | AWG 10 | Metal sleeve thickness (S1) | 0.2 mm |
| Stripping length | 24 mm | Conductor cross-section | 6 mm ² |
| Colour code | Weidmueller | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Drawing

