


H10,0/24 ZH EB

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

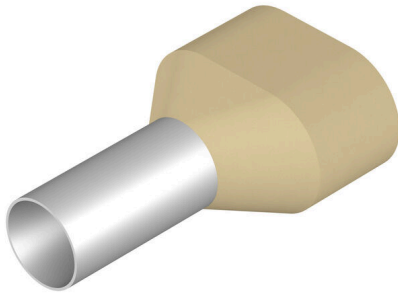

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

| | |
|------------|--|
| Version | Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, Ivory |
| Order No. | 9037340000 |
| Type | H10,0/24 ZH EB |
| GTIN (EAN) | 4008 190492816 |
| Qty. | 100 items |
| Packaging | loose |

H10,0/24 ZH EB

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



| | |
|-------------------------|----------------------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate no. (cULus) | E499744 |

Dimensions and weights

| | |
|------------|-------|
| Net weight | 0.8 g |
|------------|-------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Technical data

| | | | |
|------------------------|------------------------------|---------|-----------------------|
| Description of article | Twin wire end ferrule, ivory | Version | Twin wire-end ferrule |
|------------------------|------------------------------|---------|-----------------------|

Wire-end ferrules

| | | | |
|---|-------------|-----------------------------|--------------------|
| Contact surface diameter (D1) | 5.8 mm | Contact surface length (L2) | 12 mm |
| Collar width (B) | 7.6 mm | Collar height (A) | 13.4 mm |
| Plastic collar thickness (S2) | 0.5 mm | L1 in mm | 24.00 mm |
| Wire connection cross section AWG, max. | AWG 8 | Metal sleeve thickness (S1) | 0.2 mm |
| Stripping length | 17 mm | Conductor cross-section | 10 mm ² |
| Colour code | Weidmueller | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Drawing

