


H16,0/29 ZH GN

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

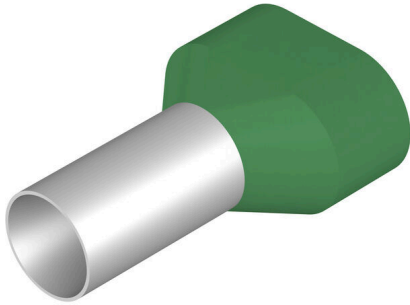

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 16 mm, green
Order No.	9037360000
Type	H16,0/29 ZH GN
GTIN (EAN)	4008 190492830
Qty.	50 items
Packaging	loose

H16,0/29 ZH GN

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 1.38 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, green	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	8.3 mm	Contact surface length (L2)	16 mm
Collar width (B)	9.5 mm	Collar height (A)	17.2 mm
Plastic collar thickness (S2)	0.6 mm	L1 in mm	29.00 mm
Wire connection cross section AWG, max.	AWG 6	Metal sleeve thickness (S1)	0.3 mm
Stripping length	20 mm	Conductor cross-section	16 mm ²
Colour code	Weidmueller		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

