

## H0,5/16D ZH W


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

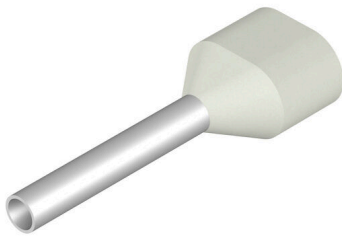

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, white
Order No.	<a href="#">9037390000</a>
Type	H0,5/16D ZH W
GTIN (EAN)	4008190492878
Qty.	500 items
Packaging	loose

**H0,5/16D ZH W**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.12 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, white	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	1.4 mm	Contact surface length (L2)	10 mm
Collar width (B)	3 mm	Collar height (A)	5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	16.00 mm
Wire connection cross section AWG, max.	AWG 20	Metal sleeve thickness (S1)	0.15 mm
Stripping length	13 mm	Conductor cross-section	0.5 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

