


## H0,75/16D ZH GR

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

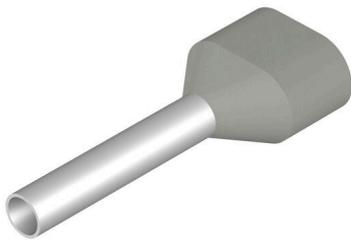

For the following conductors: 2 No. 0.75 mm<sup>2</sup> (2 No. AWG 18)

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, grey
Order No.	<a href="#">9037420000</a>
Type	H0,75/16D ZH GR
GTIN (EAN)	4008190492991
Qty.	500 items
Packaging	loose

**H0,75/16D ZH GR**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.14 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, grey	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	10 mm
Collar width (B)	3 mm	Collar height (A)	5.5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	16.00 mm
Wire connection cross section AWG, max.	AWG 18	Metal sleeve thickness (S1)	0.15 mm
Stripping length	13 mm	Conductor cross-section	0.75 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

