


## H6,0/29D ZH GE

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

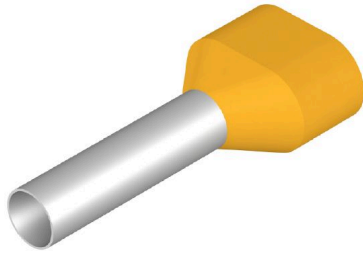

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 24 mm, 18 mm, yellow
Order No.	<a href="#">9037560000</a>
Type	H6,0/29D ZH GE
GTIN (EAN)	4008 190493 134
Qty.	100 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.72 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, yellow	Version	Twin wire-end ferrule
------------------------	-------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	4.5 mm	Contact surface length (L2)	18 mm
Collar width (B)	6.2 mm	Collar height (A)	11.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	29.00 mm
Wire connection cross section AWG, max.	AWG 10	Metal sleeve thickness (S1)	0.2 mm
Stripping length	24 mm	Conductor cross-section	6 mm <sup>2</sup>
Colour code	DIN		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01
ECLASS 13.0	27-40-02-01	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

