


## H10,0/30D ZH R

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

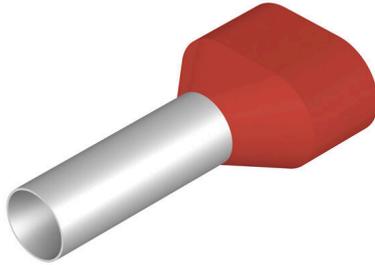

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 23 mm, 18 mm, red
Order No.	<a href="#">9037580000</a>
Type	H10,0/30D ZH R
GTIN (EAN)	4008 190493158
Qty.	100 items
Packaging	loose

**H10,0/30D ZH R**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.9 g
------------	-------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, red	Version	Twin wire-end ferrule
------------------------	----------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	5.8 mm	Contact surface length (L2)	18 mm
Collar width (B)	7.6 mm	Collar height (A)	13.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	30.00 mm
Wire connection cross section AWG, max.	AWG 8	Metal sleeve thickness (S1)	0.2 mm
Stripping length	23 mm	Conductor cross-section	10 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

