


## H16,0/29D ZH BL

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

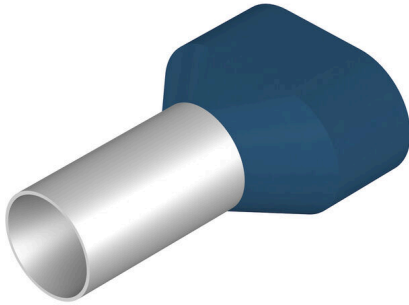

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 16 mm, blue
Order No.	<a href="#">9037590000</a>
Type	H16,0/29D ZH BL
GTIN (EAN)	4008 190493165
Qty.	50 items
Packaging	loose

**H16,0/29D ZH BL**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	1.38 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, blue	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	8.3 mm	Contact surface length (L2)	16 mm
Collar width (B)	9.5 mm	Collar height (A)	17.2 mm
Plastic collar thickness (S2)	0.6 mm	L1 in mm	29.00 mm
Wire connection cross section AWG, max.	AWG 6	Metal sleeve thickness (S1)	0.3 mm
Stripping length	20 mm	Conductor cross-section	16 mm <sup>2</sup>
Colour code	DIN		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

