


H16,0/38D ZH BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

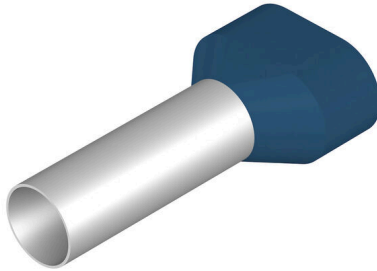

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 29 mm, 25 mm, blue
Order No.	9037600000
Type	H16,0/38D ZH BL
GTIN (EAN)	4008 190493 196
Qty.	50 items
Packaging	loose

H16,0/38D ZH BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	1.64 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, blue	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	8.3 mm	Contact surface length (L2)	25 mm
Collar width (B)	9.5 mm	Collar height (A)	17.2 mm
Plastic collar thickness (S2)	0.6 mm	L1 in mm	38.00 mm
Wire connection cross section AWG, max.	AWG 6	Metal sleeve thickness (S1)	0.3 mm
Stripping length	29 mm	Conductor cross-section	16 mm ²
Colour code	DIN		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

