


## H4,0/22T ZH OR

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

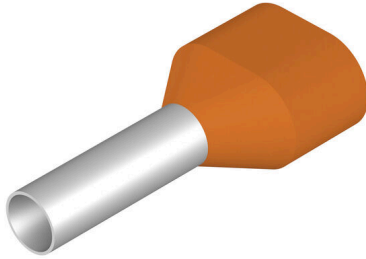

- supplied loose in poly-bag
- DIN colour code
- other colour code

### General ordering data

|            |   |
|------------|---|
| Version    | Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, orange |
| Order No.  | <a href="#">9037670000</a>                                    |
| Type       | H4,0/22T ZH OR  |
| GTIN (EAN) | 4008 19049343 1   |
| Qty.       | 100 items   |
| Packaging  | loose   |

**Technical data**

**Approvals**

Approvals



|                         |                            |
|-------------------------|----------------------------|
| ROHS                    | Conform                    |
| UL File Number Search   | <a href="#">UL Website</a> |
| Certificate no. (cULus) | E499744                    |

**Dimensions and weights**

|            |       |
|------------|-------|
| Net weight | 0.4 g |
|------------|-------|

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

**Technical data**

|                        |                               |         |                       |
|------------------------|-------------------------------|---------|-----------------------|
| Description of article | Twin wire end ferrule, orange | Version | Twin wire-end ferrule |
|------------------------|-------------------------------|---------|-----------------------|

**Wire-end ferrules**

|   |               |                             |                   |
|---|---------------|-----------------------------|-------------------|
| Contact surface diameter (D1)           | 3.5 mm        | Contact surface length (L2) | 12 mm             |
| Collar width (B)                        | 5.2 mm        | Collar height (A)           | 9 mm              |
| Plastic collar thickness (S2)           | 0.5 mm        | L1 in mm                    | 22.00 mm          |
| Wire connection cross section AWG, max. | AWG 12        | Metal sleeve thickness (S1) | 0.2 mm            |
| Stripping length                        | 15 mm         | Conductor cross-section     | 4 mm <sup>2</sup> |
| Colour code                             | Telemecanique |                             |                   |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000005    | ETIM 9.0    | EC000005    |
| ETIM 10.0   | EC000005    | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 |             |             |

Drawings

Drawing

